


Four Pole Distrib. Block with Threaded Bars, 125 A

Data Solutions

KATALOGNUMMER

TR-125A

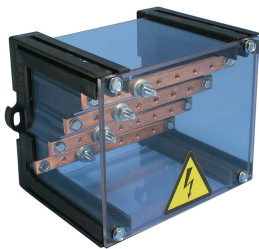

CERTIFICERINGER



FUNKTIONER

Easily clips onto DIN rail or mounts to panel with screws

Equipped with a current input plug

Bolts included for output connections

Transparent protection cover

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

PRODUKTEGENSKABER

Artikelnummer: 563150

Materiale: Copper; Glass Fibre Reinforced Polyamide; Plexiglass

Max Working Voltage, IEC (Ui): 1000

Peak Short Circuit Current (Ipk): 40kA

Short Term Withstand Current (Icw) 1s: 8.4kA

Line Side Number of Connections: 1

Load Side Number of Connections: 5

Thread Size 1 (TS1): M5

Thread Size 2 (TS2): M6

Dybde (D): 117mm

Height (H): 126mm

Width (W): 150mm

Unit Weight: 0.68kg

Flammability Rating: UL® 94V-0


Complies With: IEC® 60439.1; IEC® 61439.1; IEC® 60695-2-11 (Glow Wire Test 960 °C)

YDERLIGERE PRODUKTOPLYSNINGER

Thread Size 2 represents input plug.

Line side and load side number of connections are per pole.

DIAGRAMS

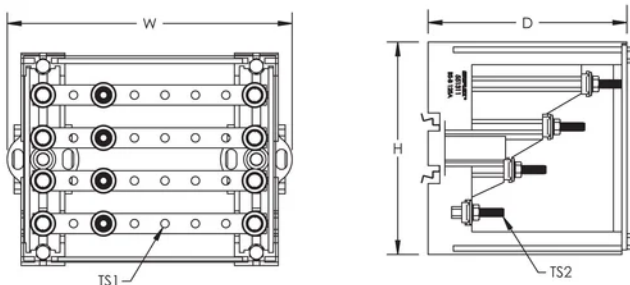

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE