

# 19" Front Panel, Vented

Vented front panels allows heat dissipation through holes.



## CERTIFICERINGER



## FUNKTIONER

Vented front panels (Aluminium ) allows heat dissipation

## SPECIFIKATIONER

<b>Rack Width:</b>	95HP
<b>Materiale:</b>	Aluminium
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel

Table 1/2

Katalognummer	Rack Height	Finish	Mounting	Pakke mængde	Front Finish	Rear Finish
30118-962	1U	Struktur Pulvermaling	Screw-on Front	1	Painted	Painted
30702-047	1U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-056	1U	Struktur Pulvermaling	Screw-on Front	1	Painted	Painted
30702-044	1U	Anodized	Screw-on Front	1	Raw	Conductive

Katalognummer	Rack Height	Finish	Mounting	Pakke mængde	Front Finish	Rear Finish
30118-963	2U	Anodized	Screw-on Front	1	Painted	Painted
30702-048	2U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-057	2U	Struktur Pulvermaling	Screw-on Front	1	Painted	Painted
30118-964	3U	Struktur Pulvermaling	Screw-on Front	1	Painted	Painted
30702-058	3U	Struktur Pulvermaling	Screw-on Front	1	Painted	Painted
30702-046	3U	Anodized	Screw-on Front	1	Raw	Raw
30702-045	2U	Anodized	Screw-on Front	1	Raw	Raw
30702-049	3U	Anodized	Screw-on Front	1	Anodized	Anodized


Table 2/2

Katalognummer	Treated Edges	Farvekode	EMC Shielding	Højde (H)	Type	Bredde (W)
30118-962		RAL 7021	No	43.6mm	19" Front Panel	483mm
30702-047	Yes		No	43.6mm	19" Front Panel	483mm
30702-056		RAL 7035	No	43.6mm	19" Front Panel	483mm
30702-044			No	43.6mm	19" Front Panel	483mm
30118-963		RAL 7021	No	88.1mm	19" Front Panel	483mm
30702-048	Yes		No	88.1mm	19" Front Panel	483mm
30702-057		RAL 7035	No	88.1mm	19" Front Panel	483mm
30118-964		RAL 7021	No	132.5mm	19" Front Panel	483mm
30702-058		RAL 7035	No	132.5mm	19" Front Panel	483mm
30702-046			No	132.5mm	19" Front Panel	483mm
30702-045			No	88.1mm	19" Front Panel	483mm
30702-049	Yes		No	132.5mm	19" Front Panel	483mm

## YDERLIGERE PRODUKTOPLYSNINGER

Please order 19" assembly kit separately.

## DIAGRAMS

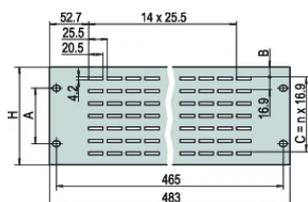

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**