


# On Board Rack

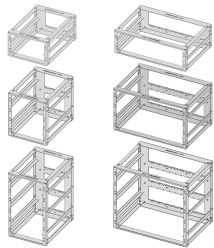

Suitable for ongoing vibrations, shock, high temperatures, and high humidity.

## CERTIFICERINGER



## FUNKTIONER

For mobile railway applications

Suitable for ongoing vibrations, shock, high temperatures, and high humidity

Suitable for 1, 2, or 3 U SNCF subracks (NF F61-005, CF 60-002)

Rear side is equipped for standard connectors; crossbar can be custom-coded for the SNCF coding pins

Crossbar with integrated cable channel

Several racks can be stacked or fitted in rows

Produced using a welding process, certified to EN 15085 (CL2)

Stainless Steel welds passivated to prevent corrosion

## SPECIFIKATIONER

|                        |                                |
|------------------------|--------------------------------|
| <b>Static Load:</b>    | 25kg                           |
| <b>Dybde:</b>          | 341.8mm                        |
| <b>Product Type:</b>   | Rack                           |
| <b>Complies With:</b>  | SNCF NFF 61005; SNCF NFF 60002 |
| <b>Frame Material:</b> | Stål                           |

Table 1/1

| Katalognummer | Rack Height | Højde   | Rack Width | Bredde   | Pakke mængde | Materiale       |
|---------------|-------------|---------|------------|----------|--------------|-----------------|
| 10170-013     | 6U          | 290mm   | 36HP       | 252.65mm | 1            | Stainless Steel |
| 10170-017     | 9U          | 423.4mm | 36HP       | 252.65mm | 1            | Stainless Steel |
| 10170-012     | 6U          | 290mm   | 84HP       | 496.4mm  | 1            | Stainless Steel |
| 10170-014     | 3U          | 156.7mm | 84HP       | 496.4mm  | 1            | Stainless Steel |
| 10170-016     | 9U          | 423.4mm | 84HP       | 496.4mm  | 1            | Stainless Steel |
| 10170-015     | 3U          | 156.7mm | 36HP       | 252.65mm | 1            | Stainless Steel |

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**