

Heavy Duty Pipe Clamp, Painted, Red Oxide, 216–222 mm OD, 8" Pipe, 200 DN

CATALOG NUMBER

SSG222RO



FEATURES

For high static requirements in industrial construction

Suitable for fix point applications

PRODUCT ATTRIBUTES

Article Number: 574700

Material: Steel

Finish: Painted;Red Oxide

Outer Diameter (OD): 216 - 222 mm

Pipe Size: 8"

NB/DN: 200

Hole Size (HS): 22 mm

Screw Diameter (Sc): 20 mm

Screw Length (L): 80mm

Static Load: 3600N

Width (W): 60 mm


Thickness (T): 8 mm

A: 290 mm

ADDITIONAL PRODUCT DETAILS

Static load refers to a complete set of Heavy Duty Pipe Clamps held in place with indicated screws per ISO 4014 and corresponding hex nuts per ISO 4032 (for further information, please refer to Standard SSG 7075E).

DIAGRAMS

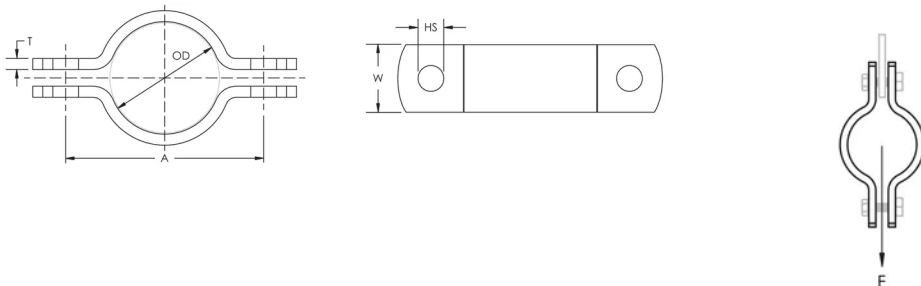

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

