

# Multi-Function C-Clamp



## FEATURES

Multi-functional beam clamp

Use with Cable/Conduit/Pipe Clamp or Square Washer for Multi-Function C-Clamp

## SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	E-Number	Material	Finish	Flange Thickness (FT)	Hole Size (HS)
C20HD	336100	1511330	Steel	Hot-Dip Galvanized	4 - 20 mm	14 mm
C20S4	336130	1511106	Stainless Steel 304 (EN 1.4301)		4 - 20 mm	14 mm
C45HD	336120	1511332	Steel	Hot-Dip Galvanized	30 - 44 mm	14 mm
C45S4	336150	1511108	Stainless Steel 304 (EN 1.4301)		30 - 44 mm	14 mm
C30S4	336140	1511107	Stainless Steel 304 (EN 1.4301)		17 - 30 mm	14 mm
C30HD	336110	1511331	Steel	Hot-Dip Galvanized	17 - 30 mm	14 mm


Table 2/2

Catalog Number	Article Number	E-Number	Screw Diameter (Sc)	Screw Length (L)	Torque (TQ)	Static Load
C20HD	336100	1511330	6	25mm	3 N·m	1100N
C20S4	336130	1511106	6	25mm	3 N·m	1100N
C45HD	336120	1511332	8	30mm	3 N·m	1100N
C45S4	336150	1511108	8	30mm	3 N·m	1100N
C30S4	336140	1511107	8	30mm	3 N·m	1100N
C30HD	336110	1511331	8	30mm	3 N·m	1100N

## ADDITIONAL PRODUCT DETAILS

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

## DIAGRAMS

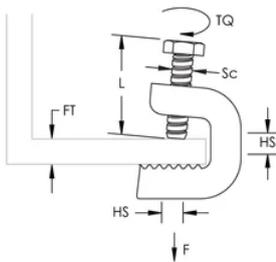

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

**Europe**

Netherlands:

+31 800-0200135

France:

+33 800 901 793

**Europe**

Germany:

800 1890272

Other Countries:

+31 13 5835404

**APAC**

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

