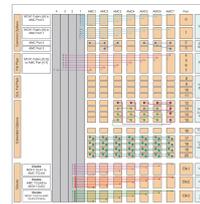


MTCA.4 Cube System for 7 Double AMC Modules, 5 U, 42 HP

NUMĂR DE CATALOG

11850-021

The system is designed for development and lab testing work. The hot-swap fan module with EMMC ensures that the front and rear slots are properly cooled at a low noise level. The fan speed is controlled independently for front and rear and is set via the MCH. The backplane features clock and trigger lines per PICMG MTCA.4, as well as interlocks. It also provides direct connections for SAS/SATA and lines between the AMCs.

CERTIFICATIONS



CARACTERISTICI

In accordance with PICMG MTCA.4 R1.0 specification

5 U, 42 HP cube system for 6 Double Mid-Size and 1 Double Full-Size AdvancedMC modules, 1 Double Full-Size MCH and 1 Double Full-Size power module

6 rear transition module slots for Double Mid-Size modules and one slot for Double Full-Size

Backplane with star topology, direct connections for S-ATA/SAS, clock and trigger lines per PICMG MTCA.4

Clock topology per PICMG AMC.0 R2.0

Hot-swap fan module with cooling unit manager (CU EMMC), airflow from bottom to top, fan speed for front and rear sections can be separately adjusted via MCH

Air filter accessible from the front

ATTRIBUTE PRODUS

Product Type: System

Number of Slots: 7

Type: Half 19" Rack Mount

Backplane Type: MTCA.4 Star Topology

Data Transfer: 40 GbE; PCIe Gen3

Power per Slot: 80W

Airflow Direction: Bottom to Top

Rack Height: 5U

Power Supply Type: (1) Double Full-size PM

Power Supply Included: No

Rear I/O: Yes

Complies With: PICMG MTCA.4 R1.0

Depth: 373.3mm

Height: 222.25mm

Net Weight: 10.35kg

Package Quantity: 1

DETALII SUPLIMENTARE DESPRE PRODUS

Modified systems available on request.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE