


# 带交流输入模块的前面板

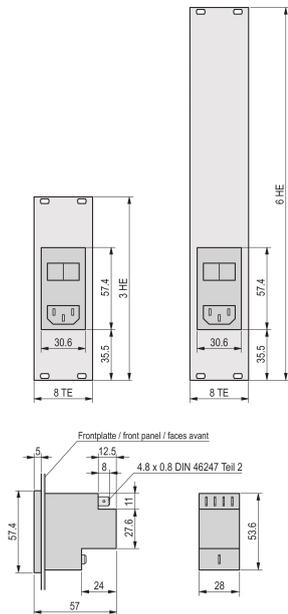

适用于 CompactPCI

系统的前面板，已安装宽幅交流输入模块，包含交流插头、熔断器支架和 EMC 过滤器。

## 认证



## 功能

电压 110 VAC ... 250 VAC, 50 Hz ... 60 Hz

前面板，通过 EMC 织物垫片进行屏蔽

40°C 时的最大电流 10 A

## 技术参数

附件类型: 前面板

Table 1/2

物料号	材料	正面表面处理	反面表面处理	机架高度	高度	机架宽度
24579-059	铝	阳极氧化	阳极氧化	3U	261.75mm	8HP
24579-058	铝	阳极氧化	导电	3U	128.4mm	8HP

Table 2/2

物料号	宽度	深度	包装数量	完成
24579-059	40.3mm	2.5mm	1	阳极氧化
24579-058	40.3mm	2.5mm	1	阳极氧化

## 其他产品详情

屏蔽型前面板需要另外安装EMC 型材密封件。

## 警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



我们强大的品牌组合:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**